

Technical data sheet

2 x BNC connection, 1 module, slanting outlet, as 1:1 coupling, black-grey

Item number: 6105105



Multimedia support with two BNC connection sockets, slanting cable outlet, with labelling panel, two BNC couplings, socket-socket version. Support plate with locking fastening, suitable for horizontal and vertical installation in the system environment.

PC Polycarbonate

Master data

Item number	6105105
Type	MTS-2BC F SWGR1
Description 1	Multimedia support, audio BNC
Description 2	2x coupling, socket-socket
Manufacturer	OBO
Dimension	45x45mm
Colour	Black-grey; RAL 7021
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	2.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1266 kg CO2e / 1 Piece


Technical data sheet

2 x BNC connection, 1 module, slanting outlet, as 1:1 coupling, black-grey

Item number: 6105105



Dimensions

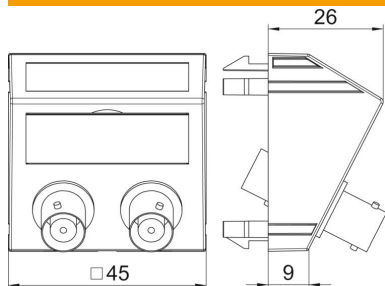

Width	45 mm
Height	45 mm

Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Protection rating	IP20
Depth	26 mm
Support ring	no
Transparent	no
Use	BNC/TNC
Strain relief option	no
Combination	Basic element with central cover plate
Outlet direction	Sloping