

Technical data sheet

BNC connection, 1 module, slanting outlet, as 1:1 coupling,
black-grey
Item number: 6105033



Multimedia support with one BNC connection socket, slanting cable outlet, with labelling panel, BNC cinch coupling, socket-socket version. Support plate with locking fastening, suitable for horizontal and vertical installation in the system environment.

PC Polycarbonate

Master data		
Item number	6105033	
Type	MTS-BC F SWGR1	
Description 1	Multimedia support, video BNC	
Description 2	1x coupling, socket-socket	
Manufacturer	OBO	
Dimension	45x45mm	
Colour	Black-grey; RAL 7021	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	1.7 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1649 kg CO2e / 1 Piece	


Technical data sheet

BNC connection, 1 module, slanting outlet, as 1:1 coupling,
black-grey

Item number: 6105033



Dimensions

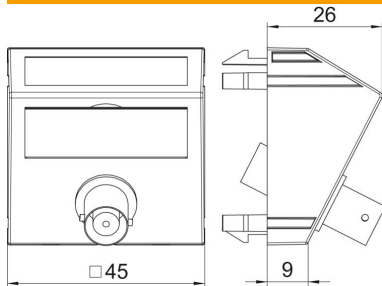

Width	45 mm
Height	45 mm

Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Protection rating	IP20
Depth	26 mm
Support ring	no
Transparent	no
Use	BNC/TNC
Strain relief option	no
Combination	Basic element with central cover plate
Outlet direction	Sloping