


Technical data sheet

D-Sub9 connection, 1 module, slanting outlet, with connection cable

Item number: 6104694



Multimedia support with one D-Sub9 connection socket, slanting cable outlet, with labelling panel, short D-Sub9 connection cable (RS232), socket-socket version. Support with locking fastening, suitable for horizontal and vertical installation in the system environment.

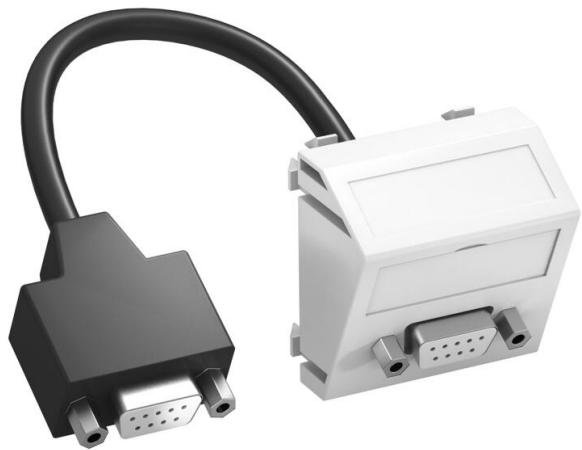

PC Polycarbonate

Master data		
Item number	6104694	
Description 1	Multimedia support, D-Sub9	
Description 2	with cable, socket-socket	
Manufacturer	OBO	
Dimension	45x45mm	
Colour	Pure white; RAL 9010	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	5.4 kg	
Weight unit	kg/100 pc.	


Technical data sheet

D-Sub9 connection, 1 module, slanting outlet, with connection cable

Item number: 6104694



Dimensions

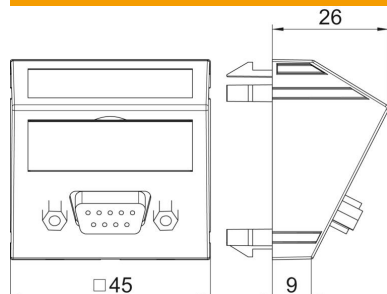

Width	45 mm
Height	45 mm

Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Labelling panel	With labelling panel
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Protection rating	IP20
Depth	26 mm
Support ring	no
Transparent	no
Use	D-Sub miniature
Strain relief option	no
Combination	Basic element with central cover plate