

# Technical data sheet

Multimedia support for DVI plug connector, 1 module, slanting outlet  
Item number: 6104796



Multimedia support for a DVI plug connector, slanting cable outlet, with labelling panel, without plug connector. Support plate with locking fastening, suitable for horizontal and vertical installation in the system environment.

PC Polycarbonate

| Master data                        |                           |  |
|------------------------------------|---------------------------|--|
| Item number                        | 6104796                   |  |
| Type                               | MTS-DV O AL1              |  |
| Description 1                      | Multimedia support, DVI   |  |
| Description 2                      | without connection socket |  |
| Manufacturer                       | OBO                       |  |
| Dimension                          | 45x45mm                   |  |
| Colour                             | Aluminium painted         |  |
| Material                           | Polycarbonate             |  |
| Smallest sales unit                | 1                         |  |
| Unit of quantity                   | Piece                     |  |
| Weight                             | 0.9 kg                    |  |
| Weight unit                        | kg/100 pc.                |  |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0304 kg CO2e / 1 Piece  |  |


# Technical data sheet

Multimedia support for DVI plug connector, 1 module, slanting outlet

Item number: 6104796



## Dimensions

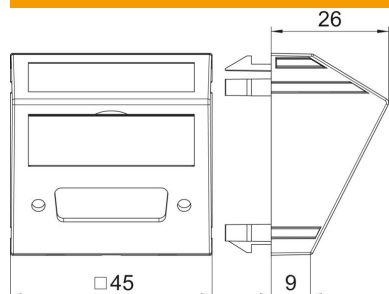

|        |       |
|--------|-------|
| Width  | 45 mm |
| Height | 45 mm |

## Technical data

|                      |                                        |
|----------------------|----------------------------------------|
| Number of units      | 1                                      |
| Surface version      | Matt                                   |
| Fastening type       | Lock                                   |
| Labelling panel      | With labelling panel                   |
| Halogen-free         | yes                                    |
| Hinged cover         | no                                     |
| Lamp-wire connector  | no                                     |
| With printed label   | no                                     |
| With dust protection | no                                     |
| Protection rating    | IP20                                   |
| Depth                | 26 mm                                  |
| Support ring         | no                                     |
| Transparent          | no                                     |
| Use                  | Miscellaneous                          |
| Strain relief option | no                                     |
| Combination          | Basic element with central cover plate |