

# Technical data sheet

Video cinch connection, 1 module, slanting outlet, as 1:1 coupling, aluminium-painted  
Item number: 6105012



Multimedia support with one cinch connection socket for composite video, slanting cable outlet, with labelling panel, cinch coupling (RCA), socket-socket version, colour coding yellow. Support plate with locking fastening, suitable for horizontal and vertical installation in the system environment.

**PC** Polycarbonate

## Master data


|                                    |                                |
|------------------------------------|--------------------------------|
| Item number                        | 6105012                        |
| Type                               | MTS-R F AL1                    |
| Description 1                      | Multimedia support video cinch |
| Description 2                      | 1x coupling, socket-socket     |
| Manufacturer                       | OBO                            |
| Dimension                          | 45x45mm                        |
| Colour                             | Aluminium painted              |
| Material                           | Polycarbonate                  |
| Smallest sales unit                | 1                              |
| Unit of quantity                   | Piece                          |
| Weight                             | 1.7 kg                         |
| Weight unit                        | kg/100 pc.                     |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0443 kg CO2e / 1 Piece       |

# Technical data sheet

Video cinch connection, 1 module, slanting outlet, as 1:1 coupling, aluminium-painted  
Item number: 6105012



## Dimensions

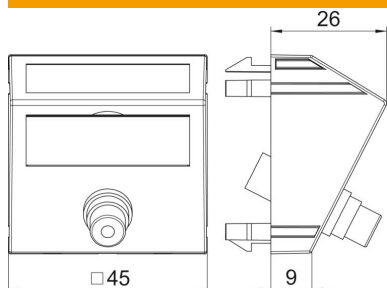

|        |       |
|--------|-------|
| Width  | 45 mm |
| Height | 45 mm |

## Technical data

|                      |                                        |
|----------------------|----------------------------------------|
| Number of units      | 1                                      |
| Surface version      | Matt                                   |
| Fastening type       | Lock                                   |
| Halogen-free         | yes                                    |
| Hinged cover         | no                                     |
| Lamp-wire connector  | no                                     |
| With printed label   | no                                     |
| With dust protection | no                                     |
| Protection rating    | IP20                                   |
| Depth                | 26 mm                                  |
| Support ring         | no                                     |
| Transparent          | no                                     |
| Use                  | Cinch                                  |
| Strain relief option | no                                     |
| Combination          | Basic element with central cover plate |