

Technical data sheet

USB 2.0/3.0 connection, 1 module, slanting outlet, as screw connection

Item number: 6104886



Multimedia support with one USB 3.0 connection socket, slanting cable outlet, with labelling panel, USB 3.0 type A socket with screw connection. Support plate with locking fastening, suitable for horizontal and vertical installation in the system environment.

PC Polycarbonate

Master data

| | |
|---------------------|-------------------------------|
| Item number | 6104886 |
| Description 1 | Multimedia support, USB 3.0 A |
| Description 2 | socket with screw connection |
| Manufacturer | OBO |
| Dimension | 45x45mm |
| Colour | Pure white; RAL 9010 |
| Material | Polycarbonate |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 2.7 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

USB 2.0/3.0 connection, 1 module, slanting outlet, as screw connection

Item number: 6104886



Dimensions

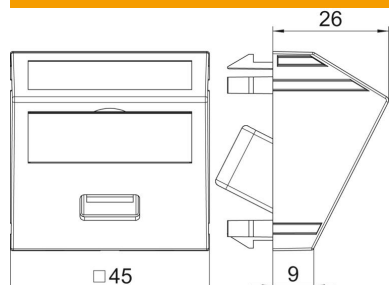

| | |
|--------|-------|
| Width | 45 mm |
| Height | 45 mm |

Technical data

| | |
|----------------------|--|
| Number of units | 1 |
| Surface version | Matt |
| Fastening type | Lock |
| Labelling panel | With labelling panel |
| Halogen-free | yes |
| Hinged cover | no |
| Lamp-wire connector | no |
| With printed label | yes |
| With dust protection | no |
| Protection rating | IP20 |
| Depth | 26 mm |
| Support ring | no |
| Transparent | no |
| Use | USB |
| Strain relief option | no |
| Combination | Basic element with central cover plate |