

Technical data sheet

Installation socket, double, NF

Item number: 7408834



Installation socket for GES R2 floor socket for mounting in UD GES R2 screed box and in raised floor plates with an installation opening diameter of 122 mm.

The scope of delivery contains a double socket (NF). Up to two modular data sockets (Keystones) can be installed with optional mounting plate.



PA

Polyamide

Master data	
Item number	7408834
Type	MT R2 NF
Description 1	Mounting support for GES R2
Description 2	with two times NF
Manufacturer	OBO
Colour	Graphite black; RAL 9011
Material	Polyamide
Smallest sales unit	1
Unit of quantity	Piece
Weight	21 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	3,1441 kg COe / 1 Piece


# Technical data sheet

## Installation socket, double, NF

Item number: 7408834



### Dimensions

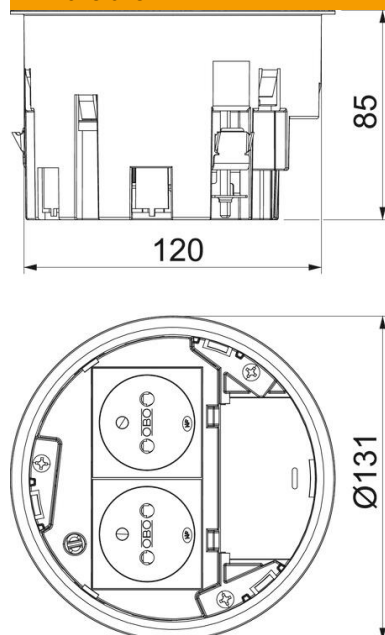

### Technical data

Number of installable devices	2
Number of strain reliefs	1
Equipment	Double LF socket
Floor covering protection frame	no
Cover version	Round
Seal installation option	yes
Suitable for raised floor installation	yes
Suitable for cavity floor installation	yes
Suitable for wet care	no
Suitable for underfloor ducts	no
Device type	Grid M45
Device support to accept mounting boxes	no
Installation technology	Grid M45
With floor covering recess	no
Clamping range D, max.	50 mm
Clamping range D, min.	25 mm
Strain relief option	yes