

Technical data sheet

Nail anchor N with thread, V4A

Item number: 3498399



The nail anchor N can be used for multiple fastenings of non-load-bearing systems, indoors and outdoors, in cracked and non-cracked concrete, thereby combining the benefits of a bolt tie with even easier mounting. The nail anchor only needs to be hammered into the drill hole. It is not necessary to apply torque subsequently. When the load occurs, the nail anchor spreads itself and bolts itself in the drill hole.

European technical approval ETA-11/0240, including characteristic values under fire exposure to fire resistance R 120.



A4	Stainless steel
2B	Bright, treated

Master data

Item number	3498399
Description 1	Nail anchor N
Description 2	with thread M6
Manufacturer	OBO
Dimension	6x49mm
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	1.2 kg
Weight unit	kg/100 pc.


Technical data sheet

Nail anchor N with thread, V4A

Item number: 3498399



Dimensions

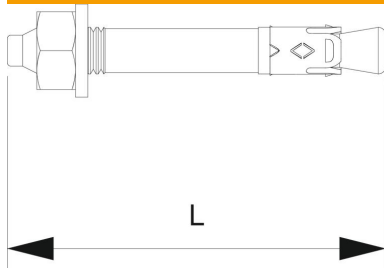

Length	49 mm
Dimension L	49 mm

Technical data

Version for	Lightning strike
Fastening unit	Miscellaneous
Drill hole depth	40 mm
Drill hole diameter, min.	6 mm
Thread	M6
Thread metric	6
Clamping strength	5 mm
WAF	10
Self-drilling	no
Approvals available	yes
Suitable for material	Concrete
Mounting type, anchor, tie	Push-through mounting