


Technical data sheet

Cover clip for WDKH trunking, trunking width 90 mm

Item number: 6176125



Cover clip for better and easier laying of lines in the WDKH trunking.

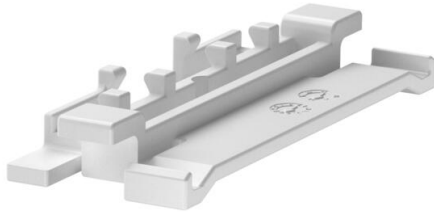


Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6176125
Type	OTK H90
Description 1	Cover fixing device
Description 2	halogen-free
Manufacturer	OBO
Dimension	75,5x29
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.9 kg
Weight unit	kg/100 pc.

Dimensions

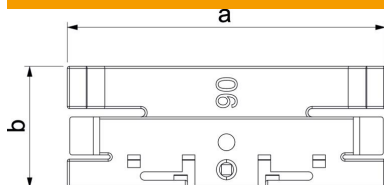

Length	28.8 mm
Width	75.7 mm
Height	10.5 mm
Dimension a	75.7 mm
Dimension b	28.8 mm

Technical data sheet

Cover clip for WDKH trunking, trunking width 90 mm

Item number: 6176125



Technical data

Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	yes
With equipotential bonding	no
Cover width	90 mm
Protection rating	IP30
Protection rating IK code	IK07.
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C