


# Technical data sheet

## Internal corner cover, Soft

Item number: 6115885



Trunking cover for the internal corner of the design device installation trunking of the GAD series. "Soft" design version for complete coverage of the system opening and the switching and plug-in devices.  
Standard version in anodised aluminium, different decoration on request.

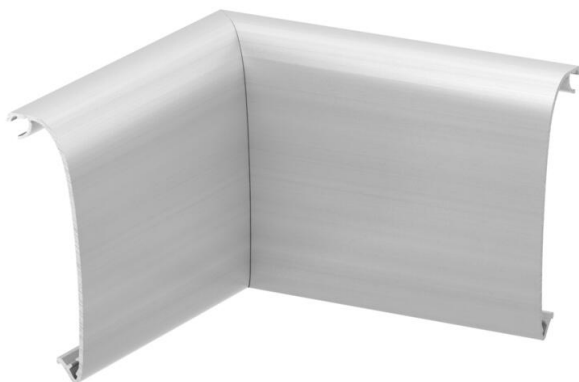

**Alu** Aluminium

**EL** Anodised

### Master data

Item number	6115885
Type	OT I Soft EL
Description 1	Cover ext. corner Design duct
Description 2	Design Soft
Manufacturer	OBO
Dimension	45x140x218
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	46.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	7,9824 kg CO2e / 1 Piece


# Technical data sheet

## Internal corner cover, Soft

Item number: 6115885



### Dimensions

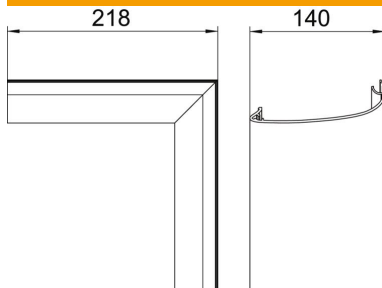

Length	218 mm
Width	140 mm
Height	45 mm

### Technical data

Application	Internal corner
Version for	Miscellaneous
Shape	Asymmetrical
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Cross-over
Mounting perforation in base	no
Protective film	yes
Angle range, max.	90 mm
Angle range, min.	90 mm