


Technical data sheet

Internal corner cover, Swing

Item number: 6115875



Trunking cover for the internal corner of the design device installation trunking of the GAD series. "Swing" design version for complete coverage of the system opening and the switching and plug-in devices.
Standard version in anodised aluminium, different decoration on request.

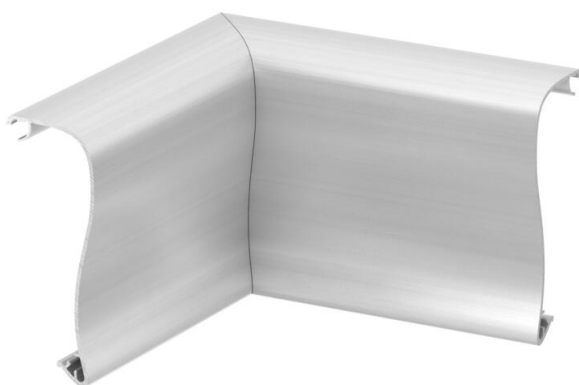

Alu	Aluminium
EL	Anodised

Master data

Item number	6115875
Type	OT I Swing EL
Description 1	Cover ext. corner Design duct
Description 2	Design Swing
Manufacturer	OBO
Dimension	52x140x218
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	45.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	7,9918 kg CO2e / 1 Piece


Technical data sheet

Internal corner cover, Swing

Item number: 6115875



Dimensions

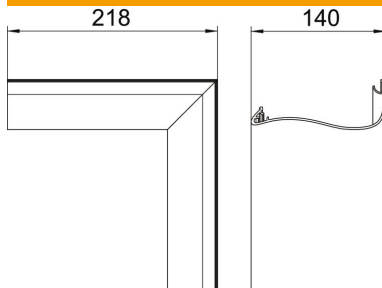

Length	218 mm
Width	140 mm
Height	52 mm

Technical data

Application	Internal corner
Version for	Miscellaneous
Shape	Asymmetrical
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Cross-over
Mounting perforation in base	no
Protective film	yes
Angle range, max.	90 mm
Angle range, min.	90 mm