


# Technical data sheet

Equipotential bonding socket, 1 module, straight outlet, pure white

Item number: 6120003



Equipotential bonding socket to DIN 42801, socket in black with green-yellow colour ring, cable connection to rear with M6 screw bolt, including two nuts, washers and a serrated washer.

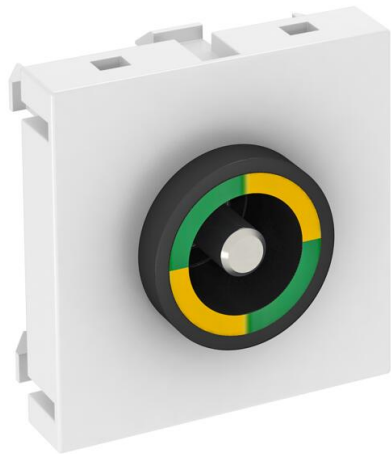

PC Polycarbonate

| Master data                       |                              |
|-----------------------------------|------------------------------|
| Item number                       | 6120003                      |
| Description 1                     | Equipotential bonding socket |
| Manufacturer                      | OBO                          |
| Dimension                         | 45x45mm                      |
| Colour                            | Pure white; RAL 9010         |
| Material                          | Polycarbonate                |
| Smallest sales unit               | 1                            |
| Unit of quantity                  | Piece                        |
| Weight                            | 5 kg                         |
| Weight unit                       | kg/100 pc.                   |
| CO Footprint (GWP) Cradle-to-Gate | 0,1122 kg COe / 1 Piece      |


# Technical data sheet

Equipotential bonding socket, 1 module, straight outlet, pure white

Item number: 6120003



## Dimensions

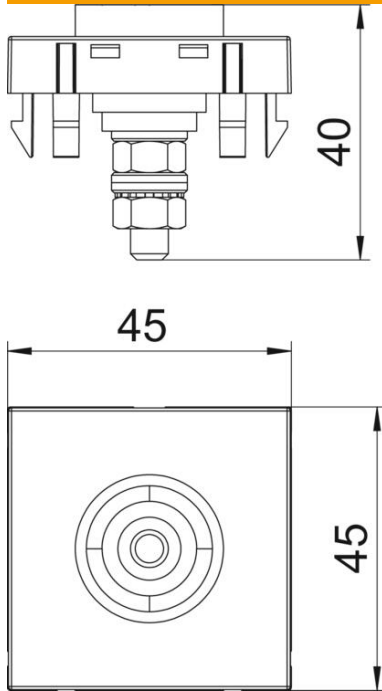

|           |         |
|-----------|---------|
| Dimension | 45 x 45 |
|-----------|---------|

## Technical data

|                 |                                        |
|-----------------|----------------------------------------|
| Surface version | Matt                                   |
| Version for     | Socket, single                         |
| Halogen-free    | yes                                    |
| Mounting type   | Installation                           |
| Transparent     | no                                     |
| Combination     | Basic element with central cover plate |