

Technical data sheet

EI60 90° bend for PLCS D060810 fire protection duct

Item number: 7217880



90° bend for PYROLINE® Con S EI60 fire protection duct, type PLCS D060810, consisting of fibreglass light concrete which is resistant to water and frost for the creation of horizontal changes of direction in the duct. Mounted connectors ensure quick mounting in situ, whilst loosely placed covers ensure quick inspection and reassignment.

Including connection screws and sealing strips.
Including connection screws and sealing strips.



Fibreglass lightweight concrete

Master data

Item number	7217880
Description 1	90° bend EI60
Description 2	for PLCS D060810
Manufacturer	OBO
Dimension	100x80
Colour	Grey
Material	Fibreglass lightweight concrete
Smallest sales unit	1
Unit of quantity	Piece
Weight	690 kg
Weight unit	kg/100 pc.


Technical data sheet

EI60 90° bend for PLCS D060810 fire protection duct

Item number: 7217880



Dimensions

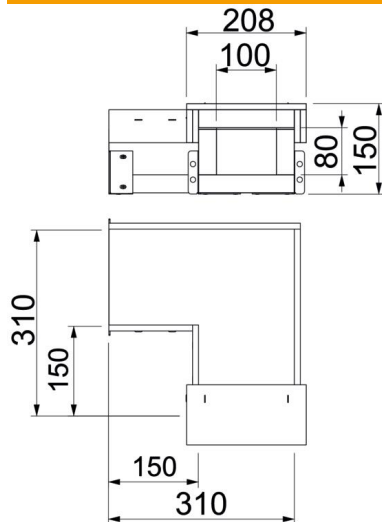

External dimensions	208 x 150
Internal dimensions	100 x 80
Dimension B	208 mm
Dimension b	100 mm
Dimension h	80 mm
Dimension H	150 mm
Dimension L	310 mm

Technical data

Number of flammable sides	4
Cover fastening	Loose
Classification EI – installation duct	60
With perforation	no
Jacketing	Without
Material of the insulation	Glass-fibre lightweight concrete
Angle of the bend	90 °