

# Technical data sheet


## EI90 90° bend for PLCS D090810 fire protection duct

Item number: 7217890



90° bend for PYROLINE® Con S EI90 fire protection duct, type PLCS D090810, consisting of fibreglass light concrete which is resistant to water and frost for the creation of horizontal changes of direction in the duct. Mounted connectors ensure quick mounting in situ, whilst loosely placed covers ensure quick inspection and reassignment.

Including connection screws and sealing strips.  
Including connection screws and sealing strips.

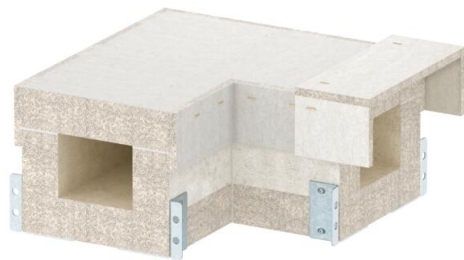

Fibreglass lightweight concrete

Master data		
Item number	7217890	
Description 1	90° bend EI90	
Description 2	for PLCS D090810	
Manufacturer	OBO	
Dimension	100x80	
Colour	Grey	
Material	Fibreglass lightweight concrete	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	1010 kg	
Weight unit	kg/100 pc.	


# Technical data sheet

## EI90 90° bend for PLCS D090810 fire protection duct

Item number: 7217890



### Dimensions

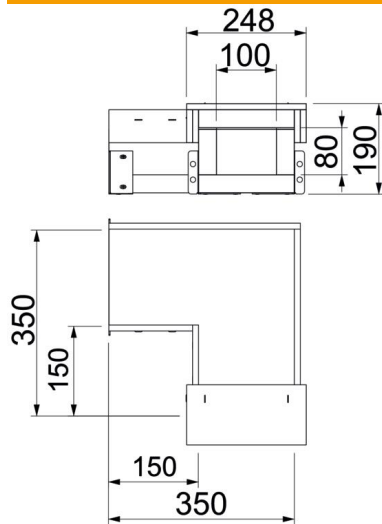

External dimensions	248 x 190
Internal dimensions	100 x 80
Dimension B	248 mm
Dimension b	100 mm
Dimension h	80 mm
Dimension H	190 mm
Dimension L	350 mm

### Technical data

Number of flammable sides	4
Cover fastening	Loose
Classification EI – installation duct	90
With perforation	no
Jacketing	Without
Material of the insulation	Glass-fibre lightweight concrete
Angle of the bend	90 °