

Technical data sheet

EI60 T piece for PLCS D060810 fire protection duct

Item number: 7217900



T piece for PYROLINE® Con S EI60 fire protection duct, type PLCS D060810, consisting of fibreglass light concrete which is resistant to water and frost, for the creation of T branches in the duct route. Mounted connectors ensure quick mounting in situ, whilst loosely placed covers ensure quick inspection and reassignment.

Including connection screws and sealing strips.
Including connection screws and sealing strips.



Fibreglass lightweight concrete

Master data		
Item number	7217900	
Description 1	T piece EI60	
Description 2	for PLCS D060810	
Manufacturer	OBO	
Dimension	100x80	
Colour	Grey	
Material	Fibreglass lightweight concrete	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	870 kg	
Weight unit	kg/100 pc.	


Technical data sheet

EI60 T piece for PLCS D060810 fire protection duct

Item number: 7217900



Dimensions

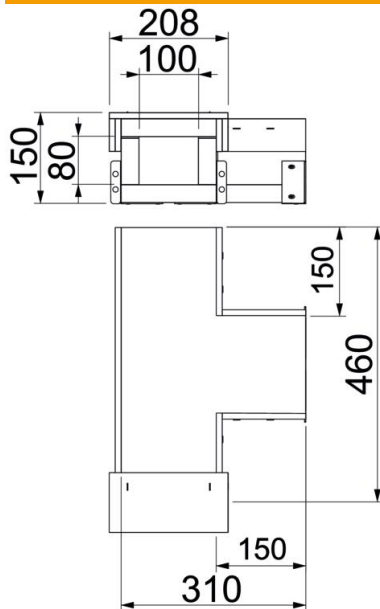

External dimensions	208 x 150
Internal dimensions	100 x 80
Dimension B	208 mm
Dimension b	100 mm
Dimension h	80 mm
Dimension H	150 mm
Dimension L	460 mm
Dimension I	310 mm

Technical data

Number of flammable sides	4
Classification EI – installation duct	60
With perforation	no
Jacketing	Without
Material of the insulation	Glass-fibre lightweight concrete