

Technical data sheet

EI60 T piece for PLCS D061220 fire protection duct

Item number: 7217904



T piece for PYROLINE® Con S EI60 fire protection duct, type PLCS D061220, consisting of fibre glass light concrete which is resistant to water and frost, for the creation of T branches of the duct. Mounted connectors ensure quick mounting in situ, whilst loosely placed covers ensure quick inspection and reassignment.

Including connection screws and sealing strips.
Including connection screws and sealing strips.



Fibreglass lightweight concrete

Master data

Item number	7217904
Type	PLCS T061220
Description 1	T piece EI60
Description 2	for PLCS D061220
Manufacturer	OBO
Dimension	200x120
Colour	Grey
Material	Fibreglass lightweight concrete
Smallest sales unit	1
Unit of quantity	Piece
Weight	1390 kg
Weight unit	kg/100 pc.


Technical data sheet

EI60 T piece for PLCS D061220 fire protection duct

Item number: 7217904



Dimensions

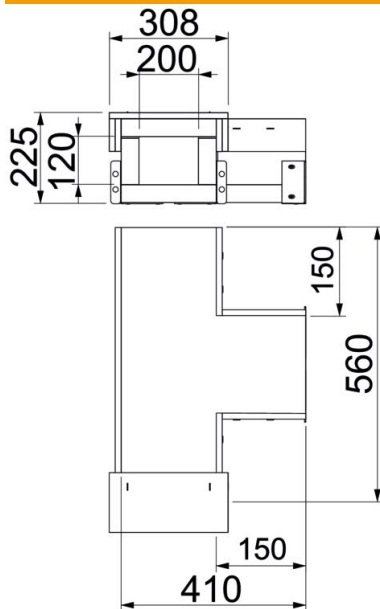

External dimensions	308 x 225
Internal dimensions	200 x 120
Dimension B	308 mm
Dimension b	200 mm
Dimension h	80 mm
Dimension H	190 mm
Dimension L	560 mm
Dimension I	410 mm

Technical data

Number of flammable sides	4
Classification EI – installation duct	60
With perforation	no
Jacketing	Without
Material of the insulation	Glass-fibre lightweight concrete