

Technical data sheet

EI90 T piece for PLCS D090810 fire protection duct

Item number: 7217910



T piece for PYROLINE® Con S EI90 fire protection duct, type PLCS D090810, consisting of fibreglass light concrete which is resistant to water and frost, for the creation of T branches in the duct route. Mounted connectors ensure quick mounting in situ, whilst loosely placed covers ensure quick inspection and reassignment.

Including connection screws and sealing strips.
Including connection screws and sealing strips.



Fibreglass lightweight concrete

Master data		
Item number	7217910	
Description 1	T piece EI90	
Description 2	for PLCS D090810	
Manufacturer	OBO	
Dimension	100x80	
Colour	Grey	
Material	Fibreglass lightweight concrete	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	1600 kg	
Weight unit	kg/100 pc.	


Technical data sheet

EI90 T piece for PLCS D090810 fire protection duct

Item number: 7217910



Dimensions

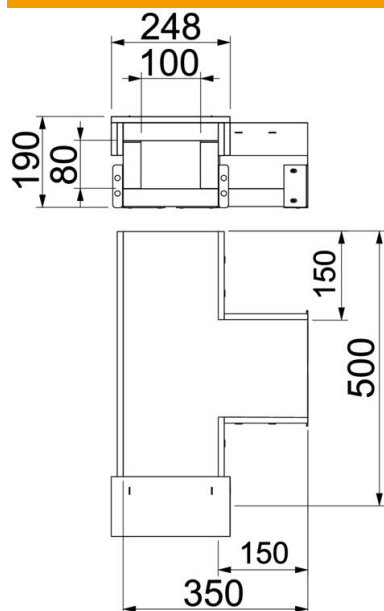

External dimensions	248 x 190
Internal dimensions	100 x 80
Dimension B	248 mm
Dimension b	100 mm
Dimension h	80 mm
Dimension H	190 mm
Dimension L	500 mm
Dimension I	350 mm

Technical data

Number of flammable sides	4
Classification EI – installation duct	90
With perforation	no
Jacketing	Without
Material of the insulation	Glass-fibre lightweight concrete