

Technical data sheet

EI90 T piece for PLCS D091220 fire protection duct

Item number: 7217914



T piece for PYROLINE® Con S EI90 fire protection duct, type PLCS D091220, consisting of fibreglass light concrete which is resistant to water and frost, for the creation of T branches in the duct route. Mounted connectors ensure quick mounting in situ, whilst loosely placed covers ensure quick inspection and reassignment.

Including connection screws and sealing strips.
Including connection screws and sealing strips.



Fibreglass lightweight concrete

Master data

Item number	7217914
Type	PLCS T091220
Description 1	T piece EI90
Description 2	for PLCS D091220
Manufacturer	OBO
Dimension	200x120
Colour	Grey
Material	Fibreglass lightweight concrete
Smallest sales unit	1
Unit of quantity	Piece
Weight	2550 kg
Weight unit	kg/100 pc.


Technical data sheet

EI90 T piece for PLCS D091220 fire protection duct

Item number: 7217914



Dimensions

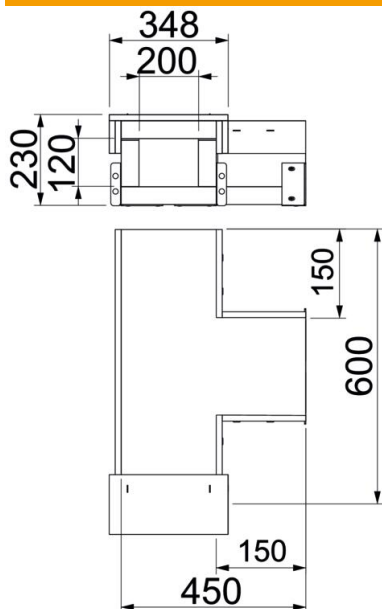

External dimensions	348 x 230
Internal dimensions	200 x 120
Dimension B	348 mm
Dimension b	200 mm
Dimension h	120 mm
Dimension H	230 mm
Dimension L	600 mm
Dimension I	450 mm

Technical data

Number of flammable sides	4
Classification EI – installation duct	90
With perforation	no
Jacketing	Without
Material of the insulation	Glass-fibre lightweight concrete