

# Technical data sheet

## Rising vertical bend EI60 for PLCS D061220 fire protection duct

Item number: 7217924



Vertical bend, rising, for PYROLINE® Con S EI60 fire protection duct, type PLCS D061220, consisting of fibreglass light concrete which is resistant to water and frost for the creation of vertical changes of direction (45°) of the duct. Mounted connectors ensure quick mounting in situ, whilst loosely placed covers ensure quick inspection and reassignment.

Including connection screws and sealing strips.  
Including connection screws and sealing strips.




Fibreglass lightweight concrete

### Master data

Item number	7217924
Description 1	Vertical bend rising EI60
Description 2	for PLCS D061220
Manufacturer	OBO
Dimension	200x120
Colour	Grey
Material	Fibreglass lightweight concrete
Smallest sales unit	1
Unit of quantity	Piece
Weight	820 kg
Weight unit	kg/100 pc.

### Dimensions

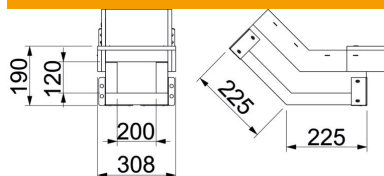

External dimensions	308 x 190
Internal dimensions	200 x 120
Dimension B	308 mm
Dimension b	200 mm
Dimension h	120 mm
Dimension H	190 mm
Dimension L	225 mm

# Technical data sheet

Rising vertical bend EI60 for PLCS D061220 fire protection duct

Item number: 7217924



## Technical data

Number of flammable sides	4
Cover fastening	Loose
Classification EI – installation duct	60
With perforation	no
Jacketing	Without
Material of the insulation	Glass-fibre lightweight concrete
Angle of the bend	45 °