

# Technical data sheet

## Metal installation duct PLMR for outdoor applications

Item number: 7218200



Installation duct made from metal with intumescent fire protection mesh. Prevents the spread of fire and protects against the impacts of cable fires. Fire resistance of up to 90 minutes. With matching fittings, obstacles in outdoor areas can be overcome easily. Suitable for the mounting on FangFix concrete block. Can be used as a special solution when laying cables over firewalls, according to expert opinion. Solution according to EltAnlagen 2020 of BMI +AMEV. Only certified pre-terminated fittings may be used. Screws included for fastening the duct cover. When used with photovoltaic cables over firewalls, this may need to be coordinated with the relevant authorities.

<b>A2</b>	Stainless steel
<b>BK</b>	Bright

### Master data

Item number	7218200
Type	PLMR 1220 A2
Description 1	Installation duct metal
Description 2	for outdoor applications
Manufacturer	OBO
Dimension	200x120x2000
Colour	stainless steel
Material	Stainless steel
Surface	Bright
Surface standard	
Smallest sales unit	2
Unit of quantity	Metre
Weight	663 kg
Weight unit	kg/100 m


# Technical data sheet

## Metal installation duct PLMR for outdoor applications

Item number: 7218200



### Dimensions

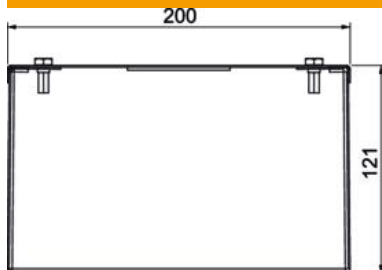

Length	2,000 mm
Width	200 mm
Height	120 mm
Dimension B	200 mm
Dimension H	121 mm

### Technical data

Number of flammable sides	4
Cover fastening	Screw
Usable cross-section	18500 mm <sup>2</sup>