

# Technical data sheet

External corner, duct height 40 mm, FS

Item number: 7218038



External corner with intumescent fire protection mesh for PYROLINE® Rapid PLM installation duct. Suitable for direct wall and ceiling mounting, mounting below system floors and on support systems. Tool-free joint mounting with PLM SI joint connector. The cover is snapped on without tools, allowing rapid inspection and retroassignment. The cover overhang allows offset cover mounting for continuous equipotential bonding of the entire duct section.



<b>St</b>	Steel
<b>FS</b>	Strip galvanized

## Master data

Item number	7218038
Type	PLM EC 0410 FS
Description 1	External corner
Description 2	with fire protection mesh
Manufacturer	OBO
Dimension	320x100x320
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	135 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,8162 kg COe / 1 Piece


# Technical data sheet

External corner, duct height 40 mm, FS

Item number: 7218038



## Dimensions

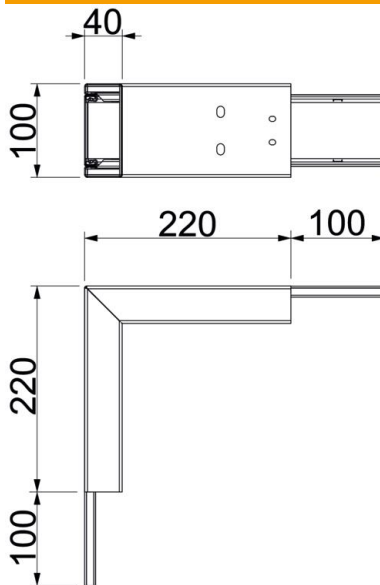

Dimension A	220 mm
Dimension B	100 mm
Dimension H	40 mm

## Technical data

Number of flammable sides	4
Cover fastening	Miscellaneous
With perforation	yes
Usable cross-section	1780 mm <sup>2</sup>
Partitions possible	no
Angle of the bend	90 °