

Technical data sheet

Flat angle, duct height 40 mm, pure white

Item number: 7218064



Flat angle with intumescent fire protection mesh for PYROLINE® Rapid PLM installation duct. Suitable for direct wall and ceiling mounting, mounting below system floors and on support systems. Tool-free joint mounting with PLM SI joint connector. The cover is snapped on without tools, allowing rapid inspection and retroassignment. The cover overhang allows offset cover mounting for continuous equipotential bonding of the entire duct section.



St	Steel
P	Powder-coated

Master data

Item number	7218064
Type	PLM FA 0410 RW
Description 1	Flat angle
Description 2	with fire protection mesh
Manufacturer	OBO
Dimension	350x350x40
Colour	Pure white; RAL 9010
Material	Steel
Surface	Powder-coated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	135 kg
Weight unit	kg/100 pc.


Technical data sheet

Flat angle, duct height 40 mm, pure white

Item number: 7218064



Dimensions

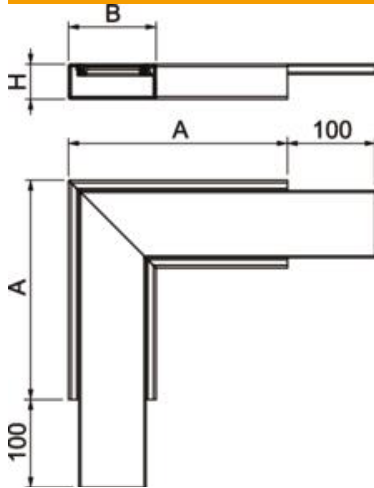

Dimension A	250 mm
Dimension B	100 mm
Dimension H	40 mm

Technical data

Number of flammable sides	4
Cover fastening	Miscellaneous
Classification EI - installation duct	90
With perforation	yes
Usable cross-section	1780 mm ²
Partitions possible	no
Jacketing	Steel
Angle of the bend	90 °