

# Technical data sheet

T branch piece, duct height 40 mm, FS

Item number: 7218074



Tee with intumescent fire protection mesh for PYROLINE® Rapid PLM installation duct. Suitable for direct wall and ceiling mounting, mounting below system floors and on support systems. Tool-free joint mounting with PLM SI joint connector. The cover is snapped on without tools, allowing rapid inspection and retroas-  
signment. The cover overhang allows offset cover mounting for continuous equipotential bonding of the entire duct section.



St	Steel
FS	Strip galvanized

## Master data

Item number	7218074
Type	PLM TB 0410 FS
Description 1	T-branch
Description 2	with fire protection mesh
Manufacturer	OBO
Dimension	500x300x40
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	135.8 kg
Weight unit	kg/100 pc.


# Technical data sheet

T branch piece, duct height 40 mm, FS

Item number: 7218074



## Dimensions

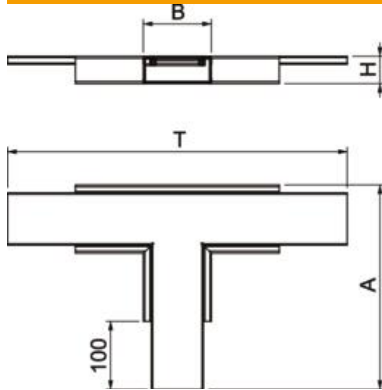

Dimension A	300 mm
Dimension B	100 mm
Dimension H	40 mm
Dimension t	500 mm

## Technical data

Number of flammable sides	4
Classification EI – installation duct	90
With perforation	yes
Usable cross-section	1780 mm <sup>2</sup>
Partitions possible	yes
Jacketing	Steel