

# Technical data sheet

T branch piece, duct height 40 mm, pure white

Item number: 7218076



Tee with intumescent fire protection mesh for PYROLINE® Rapid PLM installation duct. Suitable for direct wall and ceiling mounting, mounting below system floors and on support systems. Tool-free joint mounting with PLM SI joint connector. The cover is snapped on without tools, allowing rapid inspection and retroassignment. The cover overhang allows offset cover mounting for continuous equipotential bonding of the entire duct section.



<b>St</b>	Steel
<b>P</b>	Powder-coated

## Master data

Item number	7218076
Type	PLM TB 0410 RW
Description 1	T-branch
Description 2	with fire protection mesh
Manufacturer	OBO
Dimension	500x300x40
Colour	Pure white; RAL 9010
Material	Steel
Surface	Powder-coated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	135.8 kg
Weight unit	kg/100 pc.


# Technical data sheet

T branch piece, duct height 40 mm, pure white

Item number: 7218076



## Dimensions

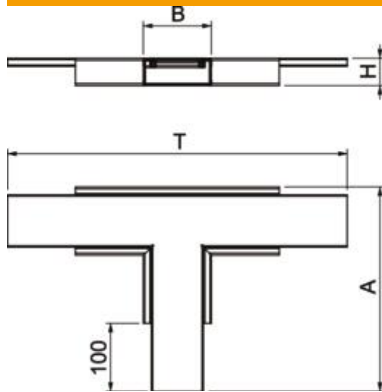

Dimension A	300 mm
Dimension B	100 mm
Dimension H	40 mm
Dimension t	500 mm

## Technical data

Number of flammable sides	4
Classification EI – installation duct	90
With perforation	yes
Usable cross-section	1780 mm <sup>2</sup>
Partitions possible	yes
Jacketing	Steel