

# Technical data sheet

T branch piece, duct height 80 mm, pure white

Item number: 7218080



Tee with intumescent fire protection mesh for PYROLINE® Rapid PLM installation duct. Suitable for direct wall and ceiling mounting, mounting below system floors and on support systems. Tool-free joint mounting with PLM SI joint connector. The cover is snapped on without tools, allowing rapid inspection and retroas-  
signment. The cover overhang allows offset cover mounting for continuous equipotential bonding of the entire duct section.



<b>St</b>	Steel
<b>P</b>	Powder-coated

## Master data

Item number	7218080
Type	PLM TB 0810 RW
Description 1	T-branch
Description 2	with fire protection mesh
Manufacturer	OBO
Dimension	500x300x80
Colour	Pure white; RAL 9010
Material	Steel
Surface	Powder-coated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	165 kg
Weight unit	kg/100 pc.


# Technical data sheet

T branch piece, duct height 80 mm, pure white

Item number: 7218080



## Dimensions

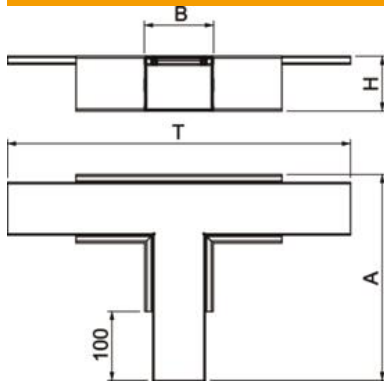

Dimension A	300 mm
Dimension B	100 mm
Dimension H	80 mm
Dimension t	500 mm

## Technical data

Number of flammable sides	4
Classification EI – installation duct	90
With perforation	yes
Usable cross-section	5180 mm <sup>2</sup>
Partitions possible	yes
Jacketing	Steel