

Technical data sheet

T branch piece, duct height 120 mm, pure white

Item number: 7218084



Tee with intumescent fire protection mesh for PYROLINE® Rapid PLM installation duct. Suitable for direct wall and ceiling mounting, mounting below system floors and on support systems. Tool-free joint mounting with PLM SI joint connector. The cover is snapped on without tools, allowing rapid inspection and retroas- signment. The cover overhang allows offset cover mounting for continuous equipotential bonding of the entire duct section.



| | |
|-----------|---------------|
| St | Steel |
| P | Powder-coated |

Master data

| | |
|---------------------|---------------------------|
| Item number | 7218084 |
| Type | PLM TB 1220 RW |
| Description 1 | T-branch |
| Description 2 | with fire protection mesh |
| Manufacturer | OBO |
| Dimension | 600x400x120 |
| Colour | Pure white; RAL 9010 |
| Material | Steel |
| Surface | Powder-coated |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 350 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

T branch piece, duct height 120 mm, pure white

Item number: 7218084



Dimensions

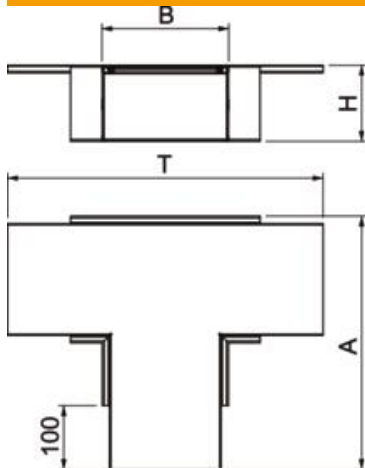

| | |
|-------------|--------|
| Dimension A | 400 mm |
| Dimension B | 200 mm |
| Dimension H | 120 mm |
| Dimension t | 600 mm |

Technical data

| | |
|---------------------------------------|-----------------------|
| Number of flammable sides | 4 |
| Classification EI - installation duct | 90 |
| With perforation | yes |
| Usable cross-section | 18500 mm ² |
| Partitions possible | yes |
| Jacketing | Steel |