

# Technical data sheet

PYROPLUG® MagicBox, three-sided, interior height 60 mm

Item number: 7204050



Fire protection box as insulation system, made of single-part stainless steel housing with intumescent fire protection inlays. Can be used in walls, on raw floors, beneath system floors and as insulation of rising sections in ceilings. Interior can be fully assigned with installations. For interior application. Closure of the residual openings with PYROSIT® NG fire protection foam, particularly simple for difficult geometries. CE-labelled construction product with general type approval. Fire resistance class EI90 (fire-resistant). Including graphite strip.



- A2 Stainless steel
- 2B Bright, treated

## Master data

|                     |                             |
|---------------------|-----------------------------|
| Item number         | 7204050                     |
| Description 1       | Fire Protection Box 3-sided |
| Description 2       | with intumescent inlays     |
| Available from      | 04.10.2022                  |
| Manufacturer        | OBO                         |
| Dimension           | 300x623x116                 |
| Colour              | stainless steel             |
| Material            | Stainless steel             |
| Surface             | Bright, treated             |
| Surface standard    |                             |
| Smallest sales unit | 1                           |
| Unit of quantity    | Piece                       |
| Weight              | 536.7 kg                    |
| Weight unit         | kg/100 pc.                  |


# Technical data sheet

PYROPLUG® MagicBox, three-sided, interior height 60 mm

Item number: 7204050



## Dimensions

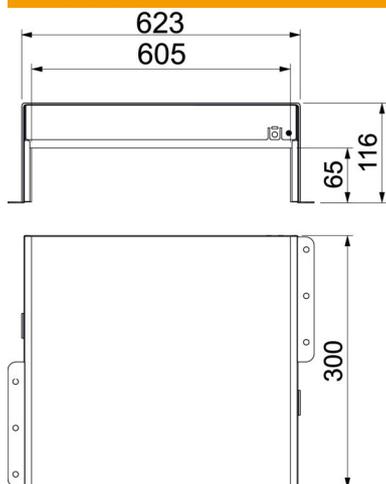

|                  |        |
|------------------|--------|
| Length           | 300 mm |
| Width            | 623 mm |
| Height           | 116 mm |
| Dimension d      | 605 mm |
| Dimension d min. | 623 mm |

## Technical data

|                         |             |
|-------------------------|-------------|
| Fire protection version | Box body    |
| Shape                   | Rectangular |
| Accessories required    | yes         |
| Internal height         | 65 mm       |
| Internal width          | 605 mm      |