

# Technical data sheet

## proQuick clip, signal white

Item number: 2147370



Highly stressable clip for accepting plastic or metal electrical and sanitary pipes as well as the electrical installation pipe Quick pipe. Universal fastening options on walls, ceilings and steel constructions, both indoors and outdoors. Flexible clamping range of several millimetres. Toolless pipe mounting. Connectable to each other to  $\varnothing$  32 mm, also with the OBO Quick or Multi Quick clip. For variable distances and clip quantity mountable on a profile rail.



**PA** Polyamide

### Master data

|                     |                        |
|---------------------|------------------------|
| Item number         | 2147370                |
| Type                | PQ-25 SWS              |
| Description 1       | proQuick clip          |
| Manufacturer        | OBO                    |
| Dimension           | 24-28mm                |
| Colour              | Signal white; RAL 9003 |
| Material            | Polyamide              |
| Smallest sales unit | 10                     |
| Unit of quantity    | Piece                  |
| Weight              | 0.92 kg                |
| Weight unit         | kg/100 pc.             |


# Technical data sheet

proQuick clip, signal white

Item number: 2147370



## Dimensions

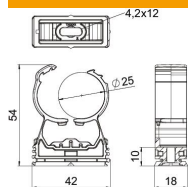

## Technical data

|                                   |            |
|-----------------------------------|------------|
| Expandable                        | yes        |
| Number of cables/pipes            | 1          |
| Fastening type                    | Screw hole |
| Breaking load                     | 0.85 kN    |
| Closed                            | yes        |
| Halogen-free                      | yes        |
| With inlay                        | no         |
| Nominal size                      | 25-28      |
| Snap system                       | yes        |
| Pipe/cable diameter, max.         | 28 mm      |
| Pipe/cable diameter, min.         | 24 mm      |
| Clamping range D, max.            | 28 mm      |
| Clamping range D, min.            | 24 mm      |
| Permitted temperature range, max. | 60 °C      |
| Permitted temperature range, min. | -15 °C     |
| UV-resistant                      | yes        |