

# Technical data sheet

## proQuick clip, light grey

Item number: 2147316



Highly stressable clip for accepting plastic or metal electrical and sanitary pipes as well as the electrical installation pipe Quick pipe. Universal fastening options on walls, ceilings and steel constructions, both indoors and outdoors. Flexible clamping range of several millimetres. Toolless pipe mounting. Connectable to each other to  $\varnothing$  32 mm, also with the OBO Quick or Multi Quick clip. For variable distances and clip quantity mountable on a profile rail.



**PA** Polyamide

### Master data

Item number	2147316
Type	PQ-32 LGR
Description 1	proQuick clip
Manufacturer	OBO
Dimension	31,2-35,8mm
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	50
Unit of quantity	Piece
Weight	1.28 kg
Weight unit	kg/100 pc.


# Technical data sheet

proQuick clip, light grey

Item number: 2147316



## Dimensions

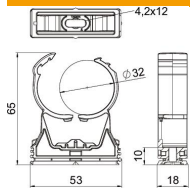

## Technical data

Expandable	yes
Number of cables/pipes	1
Fastening type	Screw hole
Breaking load	1 kN
Closed	yes
Halogen-free	yes
With inlay	no
Nominal size	32-35
Snap system	yes
Pipe/cable diameter, max.	35.5 mm
Pipe/cable diameter, min.	31.5 mm
Clamping range D, max.	35.5 mm
Clamping range D, min.	31.5 mm
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C
UV-resistant	yes