

Technical data sheet

proQuick clip, signal white

Item number: 2147374



Highly stressable clip for accepting plastic or metal electrical and sanitary pipes as well as the electrical installation pipe Quick pipe. Universal fastening options on walls, ceilings and steel constructions, both indoors and outdoors. Flexible clamping range of several millimetres. Toolless pipe mounting. Connectable to each other to \varnothing 32 mm, also with the OBO Quick or Multi Quick clip. For variable distances and clip quantity mountable on a profile rail.



PA Polyamide

Master data

Item number	2147374
Type	PQ-32 SWS
Description 1	proQuick clip
Manufacturer	OBO
Dimension	31,2-35,8mm
Colour	Signal white; RAL 9003
Material	Polyamide
Smallest sales unit	10
Unit of quantity	Piece
Weight	1.28 kg
Weight unit	kg/100 pc.


Technical data sheet

proQuick clip, signal white

Item number: 2147374



Dimensions

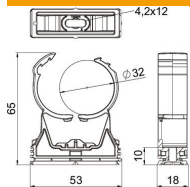

Technical data

Expandable	yes
Number of cables/pipes	1
Fastening type	Screw hole
Breaking load	1 kN
Closed	yes
Halogen-free	yes
With inlay	no
Nominal size	32-35
Snap system	yes
Pipe/cable diameter, max.	35.5 mm
Pipe/cable diameter, min.	31.5 mm
Clamping range D, max.	35.5 mm
Clamping range D, min.	31.5 mm
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C
UV-resistant	yes