


# Technical data sheet

## Add-on tee 110 FT

Item number: 6042253

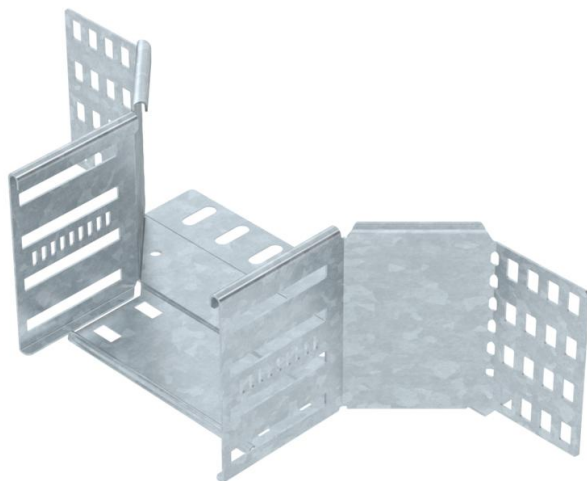

Add-on tee for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 110 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.



St

Steel

FT

Hot-dip galvanised

### Master data

|                     |                    |
|---------------------|--------------------|
| Item number         | 6042253            |
| Description 1       | Add-on tee         |
| Description 2       | for cable tray     |
| Manufacturer        | OBO                |
| Dimension           | 110x150            |
| Colour              | zinc               |
| Material            | Steel              |
| Surface             | Hot-dip galvanised |
| Surface standard    | DIN EN ISO 1461    |
| Smallest sales unit | 1                  |
| Unit of quantity    | Piece              |
| Weight              | 58.1 kg            |
| Weight unit         | kg/100 pc.         |


# Technical data sheet

## Add-on tee 110 FT

Item number: 6042253



### Dimensions

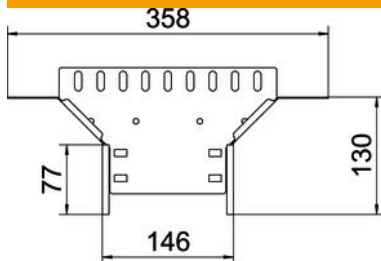

|                 |        |
|-----------------|--------|
| Width           | 150 mm |
| Height          | 110 mm |
| Plate thickness | 0.8 mm |
| Dimension B     | 150 mm |

### Technical data

|   |                      |
|---|----------------------|
| Departing width                         | 150 mm               |
| Connector version                       | Integrated connector |
| Maintain electrical functions           | no                   |
| Material thickness, floor plate         | 0.8 mm               |
| NATO hole pattern                       | no                   |
| Rustproof steel, pickled                | no                   |
| Permitted temperature range, max.       | 120 °C               |
| Permitted temperature range, min.       | -20 °C               |
| Wide-span version                       | no                   |
| Type of connector, cable support system | screwed/clamped      |
| Recommended quantity of bolts           | 18 St.               |
| Rail thickness                          | 1.25 mm              |