


Technical data sheet

Add-on tee 110 A2

Item number: 6042353



Add-on tee for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 110 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.

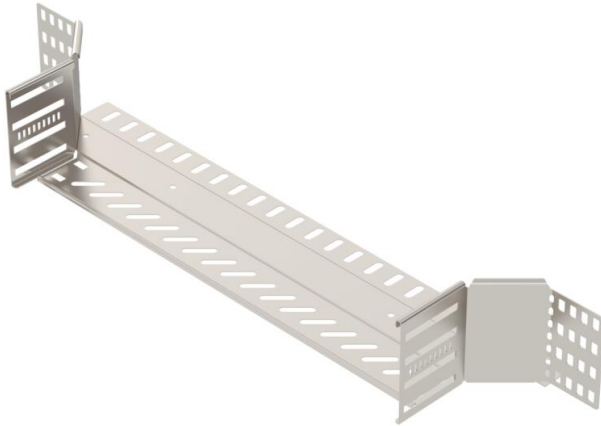

A2	Stainless steel
2B	Bright, treated

Master data

Item number	6042353
Type	RAA 150 A2
Description 1	Add-on tee
Description 2	for cable tray
Manufacturer	OBO
Dimension	110x500
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	94.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	8,4876 kg CO2e / 1 Piece


Technical data sheet

Add-on tee 110 A2

Item number: 6042353



Dimensions

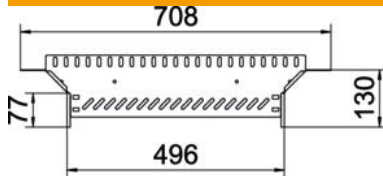

Width	500 mm
Height	110 mm
Plate thickness	1 mm
Dimension B	500 mm

Technical data

Departing width	500 mm
Connector version	Integrated connector
Maintain electrical functions	no
Material thickness, floor plate	1 mm
NATO hole pattern	no
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	screwed/clamped
Recommended quantity of bolts	24 St.
Rail thickness	1.25 mm