


Technical data sheet

Add-on tee 110 A2

Item number: 6042355



Add-on tee for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 110 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.

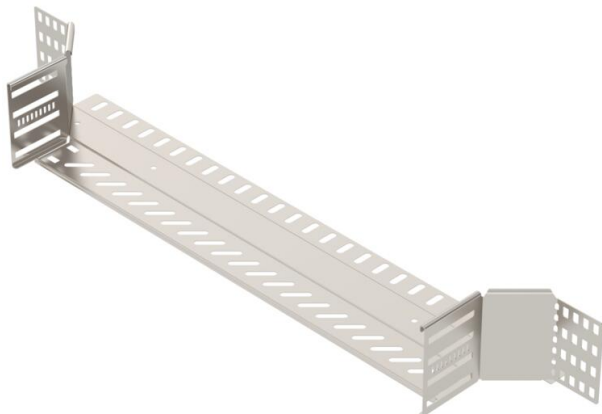

A2 Stainless steel

2B Bright, treated

Master data

| | |
|------------------------------------|--------------------------|
| Item number | 6042355 |
| Type | RAA 160 A2 |
| Description 1 | Add-on tee |
| Description 2 | for cable tray |
| Manufacturer | OBO |
| Dimension | 110x600 |
| Colour | stainless steel |
| Material | Stainless steel |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 104.8 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 9,7399 kg CO2e / 1 Piece |


Technical data sheet

Add-on tee 110 A2

Item number: 6042355



Dimensions

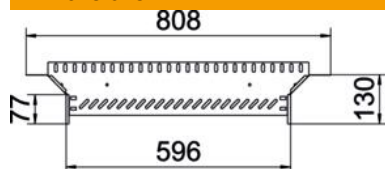

| | |
|-----------------|--------|
| Width | 600 mm |
| Height | 110 mm |
| Plate thickness | 1 mm |
| Dimension B | 600 mm |

Technical data

| | |
|---|----------------------|
| Departing width | 600 mm |
| Connector version | Integrated connector |
| Maintain electrical functions | no |
| Material thickness, floor plate | 1 mm |
| NATO hole pattern | no |
| Rustproof steel, pickled | no |
| Permitted temperature range, max. | 120 °C |
| Permitted temperature range, min. | -20 °C |
| Wide-span version | no |
| Type of connector, cable support system | screwed/clamped |
| Recommended quantity of bolts | 24 St. |
| Rail thickness | 1.25 mm |