


Technical data sheet

Mounting/branch piece 60 A4

Item number: 6042373



Add-on tee for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 60 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.

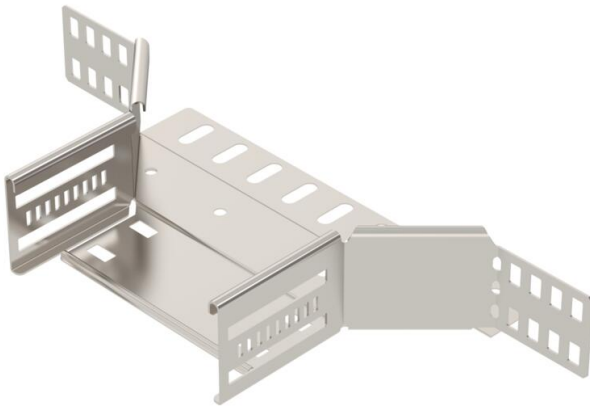

A4	Stainless steel
2B	Bright, treated

Master data

Item number	6042373
Type	RAA 615 A4
Description 1	Add-on tee
Description 2	for cable tray
Manufacturer	OBO
Dimension	60x150
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	37.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,3775 kg CO2e / 1 Piece


Technical data sheet

Mounting/branch piece 60 A4

Item number: 6042373



Dimensions

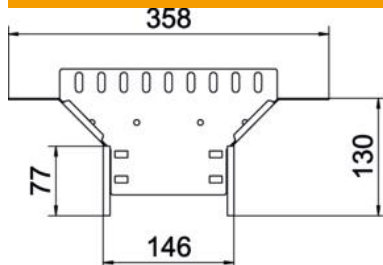

Width	150 mm
Height	60 mm
Plate thickness	0.8 mm
Dimension B	150 mm

Technical data

Departing width	150 mm
Connector version	Integrated connector
Maintain electrical functions	yes
Material thickness, floor plate	0.8 mm
NATO hole pattern	no
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	Screwed
Recommended quantity of bolts	18 St.
Rail thickness	1.25 mm