


# Technical data sheet

## Add-on tee 60 FT

Item number: 6042213



Add-on tee for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 60 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.

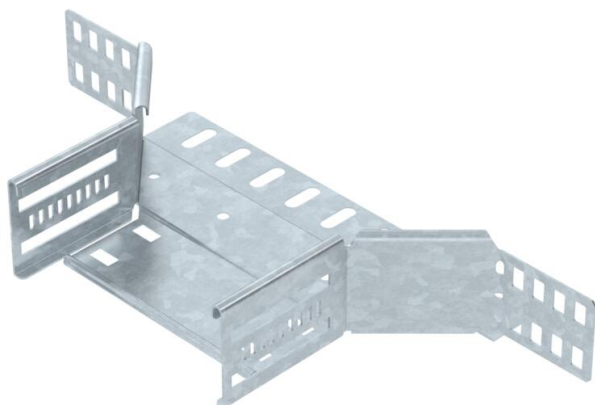

St

Steel

FT

Hot-dip galvanised

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 6042213                  |
| Type                               | RAA 615 FT               |
| Description 1                      | Add-on tee               |
| Description 2                      | for cable tray           |
| Manufacturer                       | OBO                      |
| Dimension                          | 60x150                   |
| Colour                             | zinc                     |
| Material                           | Steel                    |
| Surface                            | Hot-dip galvanised       |
| Surface standard                   | DIN EN ISO 1461          |
| Smallest sales unit                | 1                        |
| Unit of quantity                   | Piece                    |
| Weight                             | 40.1 kg                  |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,3629 kg CO2e / 1 Piece |


# Technical data sheet

## Add-on tee 60 FT

Item number: 6042213



### Dimensions

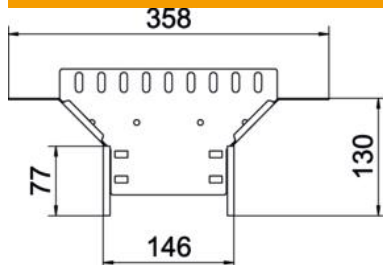

|                 |        |
|-----------------|--------|
| Width           | 150 mm |
| Height          | 60 mm  |
| Plate thickness | 0.8 mm |
| Dimension B     | 150 mm |

### Technical data

|                                         |                      |
|-----------------------------------------|----------------------|
| Departing width                         | 150 mm               |
| Connector version                       | Integrated connector |
| Maintain electrical functions           | yes                  |
| Material thickness, floor plate         | 0.8 mm               |
| NATO hole pattern                       | no                   |
| Rustproof steel, pickled                | no                   |
| Permitted temperature range, max.       | 120 °C               |
| Permitted temperature range, min.       | -20 °C               |
| Wide-span version                       | no                   |
| Type of connector, cable support system | screwed/clamped      |
| Recommended quantity of bolts           | 10 St.               |
| Rail thickness                          | 1.25 mm              |