


# Technical data sheet

## Add-on tee 60 A2

Item number: 6042321



Add-on tee for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 60 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.

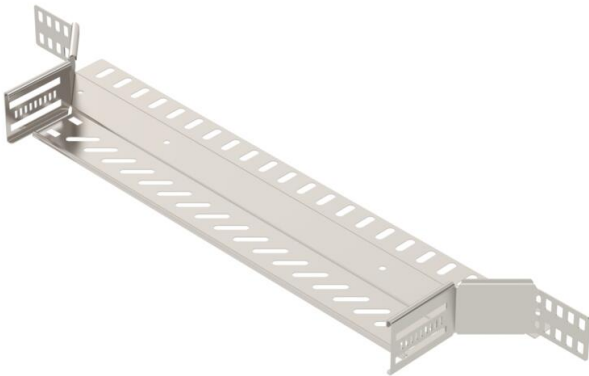

A2	Stainless steel
2B	Bright, treated

### Master data

Item number	6042321
Type	RAA 650 A2
Description 1	Add-on tee
Description 2	for cable tray
Manufacturer	OBO
Dimension	60x500
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	77.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	7,0508 kg CO2e / 1 Piece


# Technical data sheet

## Add-on tee 60 A2

Item number: 6042321



### Dimensions

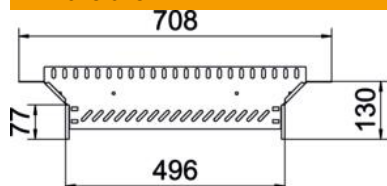

Width	500 mm
Height	60 mm
Plate thickness	1 mm
Dimension B	500 mm

### Technical data

Departing width	500 mm
Connector version	Integrated connector
Maintain electrical functions	no
Material thickness, floor plate	1 mm
NATO hole pattern	no
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	screwed/clamped
Recommended quantity of bolts	24 St.
Rail thickness	1.25 mm