


Technical data sheet

Add-on tee 60 FS

Item number: 6042121



Mounting/branch piece for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 60 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used in indoor areas. Fastening material must be ordered separately.

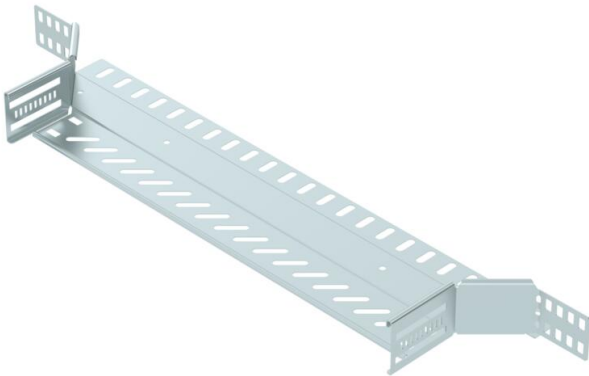

St

Steel

FS

Strip galvanized

Master data

Item number	6042121
Type	RAA 650 FS
Description 1	Add-on tee
Description 2	for cable tray
Manufacturer	OBO
Dimension	60x500
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	79.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,8765 kg CO2e / 1 Piece


Technical data sheet

Add-on tee 60 FS

Item number: 6042121



Dimensions

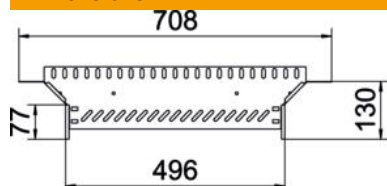

Width	500 mm
Height	60 mm
Plate thickness	1 mm
Dimension B	500 mm

Technical data

Departing width	500 mm
Connector version	Integrated connector
Maintain electrical functions	no
Material thickness, floor plate	1 mm
NATO hole pattern	no
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	screwed/clamped
Recommended quantity of bolts	16 St.
Rail thickness	1.25 mm