

# Technical data sheet

## Mounting/branch piece 60 A4

Item number: 6042383



Add-on tee for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 60 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.



**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	6042383
Type	RAA 660 A4
Description 1	Add-on tee
Description 2	for cable tray
Manufacturer	OBO
Dimension	60x600
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	88.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	8,3031 kg CO2e / 1 Piece


# Technical data sheet

## Mounting/branch piece 60 A4

Item number: 6042383



### Dimensions

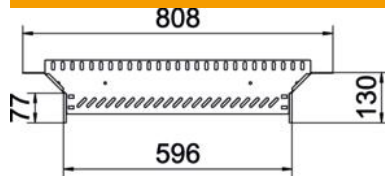

Width	600 mm
Height	60 mm
Plate thickness	1 mm
Dimension B	600 mm

### Technical data

Departing width	600 mm
Connector version	Integrated connector
Maintain electrical functions	no
Material thickness, floor plate	1 mm
NATO hole pattern	no
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	Screwed
Recommended quantity of bolts	24 St.
Rail thickness	1.25 mm