


Technical data sheet

Add-on tee 85 FT

Item number: 6042235



Add-on tee for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 85 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.

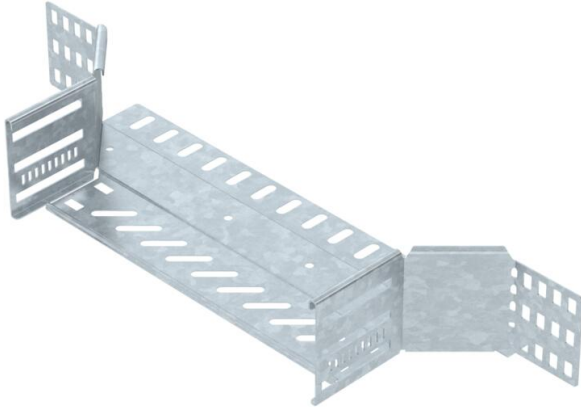

St

Steel

FT

Hot-dip galvanised

Master data

Item number	6042235
Type	RAA 830 FT
Description 1	Add-on tee
Description 2	for cable tray
Manufacturer	OBO
Dimension	85x300
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	61.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,8773 kg CO2e / 1 Piece


Technical data sheet

Add-on tee 85 FT

Item number: 6042235



Dimensions

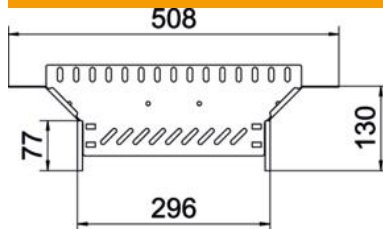

Width	300 mm
Height	85 mm
Plate thickness	0.8 mm
Dimension B	300 mm

Technical data

Departing width	300 mm
Connector version	Integrated connector
Maintain electrical functions	no
Material thickness, floor plate	0.8 mm
NATO hole pattern	no
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	screwed/clamped
Recommended quantity of bolts	18 St.
Rail thickness	1.25 mm