


# Technical data sheet

## Cover, 45° bend FS

Item number: 6036408



Cover for 45° bend fitting for lockable and screw-on cable trays in indoor areas, to protect cables against damage and soiling. Fastening with pre-mounted sash lock and through attachment of the section cover. Suitable for all side heights. The cover can be used with fittings of all side heights.

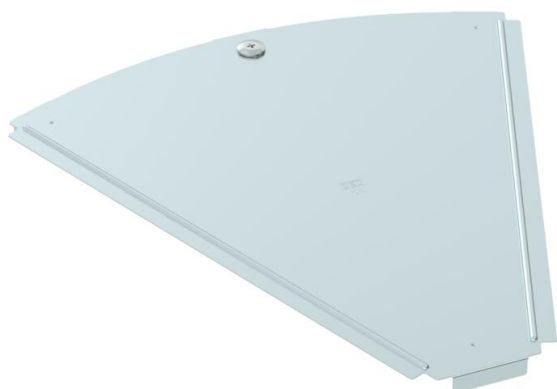

**St** Steel

**FS** Strip galvanized

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 6036408                  |
| Type                               | RBD 45 400 FS            |
| Description 1                      | Cover                    |
| Description 2                      | for 45° bend             |
| Manufacturer                       | OBO                      |
| Dimension                          | B400mm                   |
| Colour                             | zinc                     |
| Material                           | Steel                    |
| Surface                            | Strip galvanized         |
| Surface standard                   | DIN EN 10346             |
| Smallest sales unit                | 1                        |
| Unit of quantity                   | Piece                    |
| Weight                             | 83 kg                    |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 3,1973 kg CO2e / 1 Piece |


# Technical data sheet

## Cover, 45° bend FS

Item number: 6036408



### Dimensions

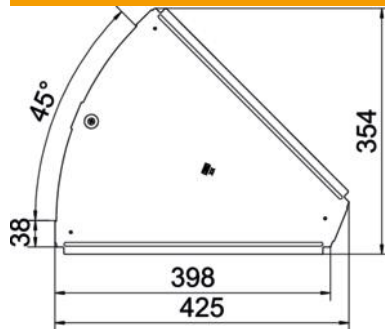

|                 |        |
|-----------------|--------|
| Length          | 425 mm |
| Width           | 400 mm |
| Plate thickness | 1 mm   |
| Dimension B     | 400 mm |

### Technical data

|                                   |            |
|-----------------------------------|------------|
| Bend (angle)                      | 45°        |
| Number of turn buckles            | 1 St.      |
| Fastening type                    | Sash lock  |
| Maintain electrical functions     | no         |
| Suitable for mesh cable tray      | no         |
| Suitable for cable ladder         | no         |
| Suitable for cable tray           | yes        |
| Change of direction               | Horizontal |
| Rustproof steel, pickled          | no         |
| Hinged                            | no         |
| Permitted temperature range, max. | 120 °C     |
| Permitted temperature range, min. | -20 °C     |