

# Technical data sheet

## Cover, 90° bend A2

Item number: 6036972



Cover for 90° bend fitting for lockable and screw-on cable trays in indoor and outdoor areas, to protect cables against damage and soiling. Fastening with pre-mounted sash lock and through attachment of the section cover. Suitable for all side heights.  
The cover can be used with fittings of all side heights.



A2	Stainless steel
2B	Bright, treated

Master data		
Item number	6036972	
Type	RBD 90 150 A2	
Description 1	Cover	
Description 2	for 90° bend	
Manufacturer	OBO	
Dimension	B150mm	
Colour	stainless steel	
Material	Stainless steel	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	24 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	2,748 kg CO2e / 1 Piece	


# Technical data sheet

## Cover, 90° bend A2

Item number: 6036972



### Dimensions

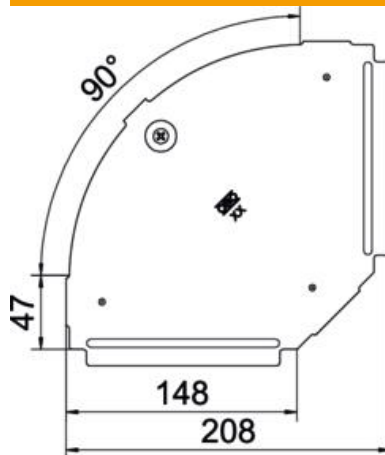

Length	207 mm
Width	150 mm
Plate thickness	0.75 mm
Dimension B	150 mm

### Technical data

Bend (angle)	90°
Number of turn buckles	1 St.
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C