


Technical data sheet

Magic bend, variable 110 FS

Item number: 6040680



Magic bend 0°–90°, variable, with quick connector system. For all cable tray types of 110 mm side height.

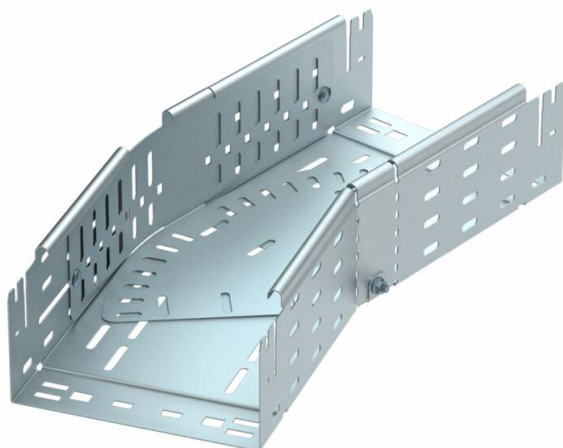

St	Steel
FS	Strip galvanized

Master data

Item number	6040680
Description 1	Variable bend
Description 2	with quick connector
Manufacturer	OBO
Dimension	110x100
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	103.9 kg
Weight unit	kg/100 pc.

Technical data sheet

Magic bend, variable 110 FS

Item number: 6040680



Dimensions

Width	100 mm
Height	110 mm
Plate thickness	1 mm
Dimension B	100 mm
Dimension L	340 mm

Technical data

Bend (angle)	Adjustable
Connector version	Integrated connector
Maintain electrical functions	no
Mounting perforation in base	yes
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	yes
Wide-span version	no
Type of connector, cable support system	Click fastening