


Technical data sheet

Magic bend, variable 60 FS

Item number: 6040492



Magic bend 0°–90°, variable, with quick connector system. For all cable tray types of 60 mm side height.

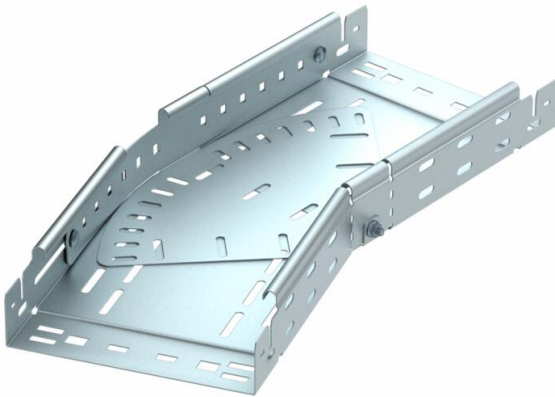

St	Steel
FS	Strip galvanized

Master data

Item number	6040492
Description 1	Variable bend
Description 2	with quick connector
Manufacturer	OBO
Dimension	60x600
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	1347.2 kg
Weight unit	kg/100 pc.

Technical data sheet

Magic bend, variable 60 FS

Item number: 6040492



Dimensions

Width	600 mm
Width	20 in
Height	60 mm
Height	2 in
Plate thickness	1.5 mm
Dimension B	600 mm
Dimension L	3.67 ft
Dimension L	1,120 mm

Technical data

Bend (angle)	Adjustable
Connector version	Integrated connector
Maintain electrical functions	no
Mounting perforation in base	yes
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	yes
Wide-span version	no
Type of connector, cable support system	Click fastening