


# Technical data sheet

## 90° vertical bend, rising, 110 FS

Item number: 7007312

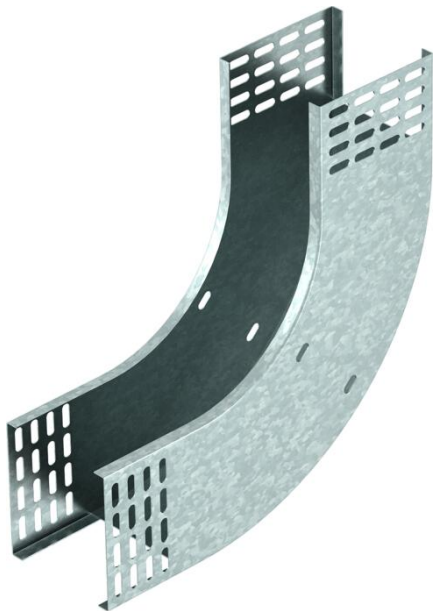

90° rising vertical bend, for all cable tray types of 110 mm side height.  
The vertical bend is pushed over the end of the cable tray and screwed tight.  
Fastening materials should be ordered separately.



|    |                  |
|----|------------------|
| St | Steel            |
| FS | Strip galvanized |

### Master data

|                     |                   |
|---------------------|-------------------|
| Item number         | 7007312           |
| Description 1       | 90° vertical bend |
| Description 2       | rising            |
| Manufacturer        | OBO               |
| Dimension           | 110x150           |
| Colour              | zinc              |
| Material            | Steel             |
| Surface             | Strip galvanized  |
| Surface standard    | DIN EN 10346      |
| Smallest sales unit | 1                 |
| Unit of quantity    | Piece             |
| Weight              | 135 kg            |
| Weight unit         | kg/100 pc.        |


# Technical data sheet

90° vertical bend, rising, 110 FS

Item number: 7007312



## Dimensions

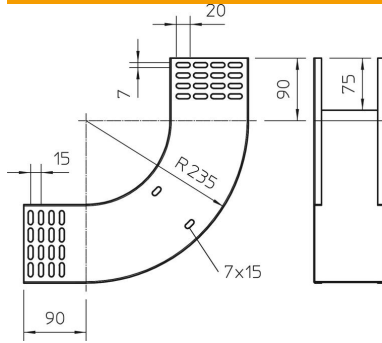

|                 |        |
|-----------------|--------|
| Width           | 150 mm |
| Height          | 110 mm |
| Height          | 4 in   |
| Plate thickness | 1 mm   |
| Dimension B     | 150 mm |

## Technical data

|                                         |                    |
|-----------------------------------------|--------------------|
| Bend (angle)                            | 90°                |
| Connector version                       | Without connectors |
| Maintain electrical functions           | no                 |
| Mounting perforation in base            | no                 |
| NATO hole pattern                       | no                 |
| Change of direction                     | Vertical rising    |
| Rustproof steel, pickled                | no                 |
| Side perforation                        | no                 |
| Wide-span version                       | no                 |
| Type of connector, cable support system | Screwed            |