


Technical data sheet

90° vertical bend, rising, 60 FT SOMY

Item number: 7195589

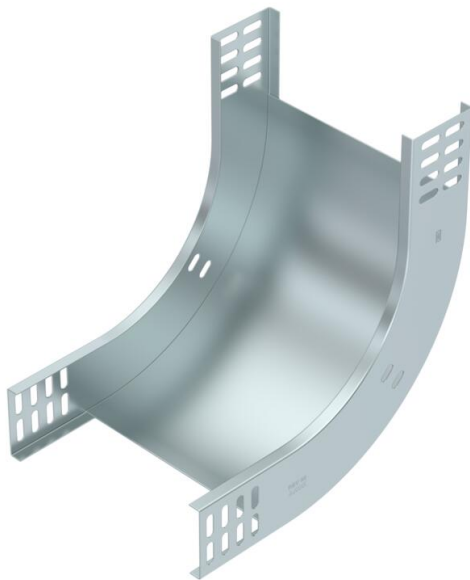

90° rising vertical bend, for all cable tray types of 60 mm side height.
The vertical bend is pushed over the end of the cable tray and screwed tight.
Fastening materials should be ordered separately.



St

Steel

FT
SO

Hot-dip galvanised 85 µm

Master data

Item number	7195589
Type	RBV 630 S FT SO
Description 1	90° vertical bend
Description 2	rising
Manufacturer	OBO
Dimension	60x300
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised 85 µm
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	143 kg
Weight unit	kg/100 pc.


Technical data sheet

90° vertical bend, rising, 60 FT SOMY

Item number: 7195589



Dimensions

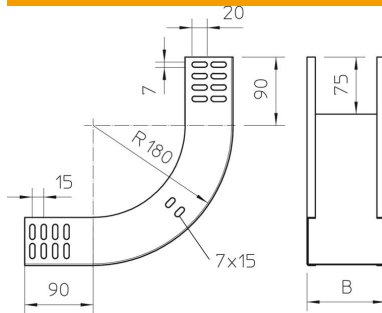

Width	300 mm
Height	60 mm
Dimension B	300 mm

Technical data

Bend (angle)	90°
Connector version	Without connectors
Type	Bend, rigid
Maintain electrical functions	no
Mounting perforation in base	no
NATO hole pattern	no
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Screwed