


Technical data sheet

90° vertical bend, falling, FT SOMY

Item number: 7195586

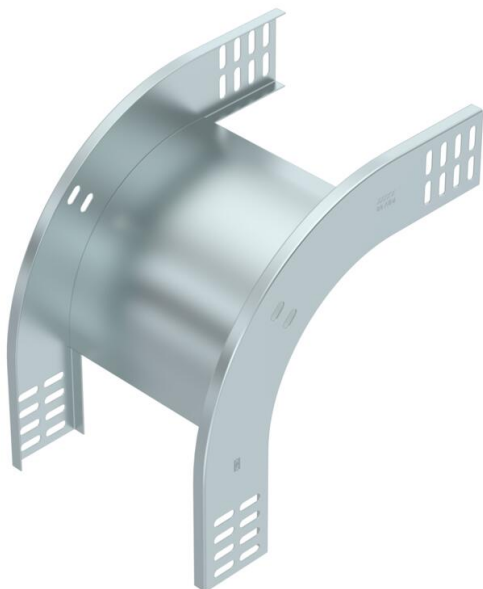

Cover for 90° bend with premounted turn buckles.
The cover can be used with fittings of all side heights.



St	Steel
FT SO	Hot-dip galvanised 85 µm

Master data

Item number	7195586
Type	RBV 640 F FT SO
Description 1	90° vertical bend
Description 2	falling
Manufacturer	OBO
Dimension	60x400
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised 85 µm
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	140 kg
Weight unit	kg/100 pc.


Technical data sheet

90° vertical bend, falling, FT SOMY

Item number: 7195586



Dimensions

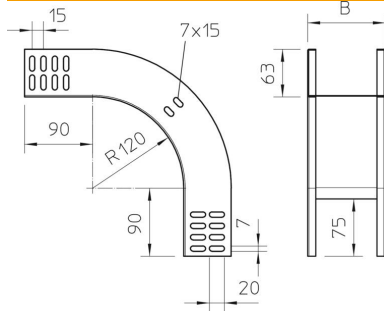

Width	400 mm
Height	60 mm
Dimension B	400 mm

Technical data

Bend (angle)	90°
Connector version	Without connectors
Type	Bend, rigid
Maintain electrical functions	no
Mounting perforation in base	no
NATO hole pattern	no
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Screwed