

# Technical data sheet

45° bend 35 FT

Item number: 6036014



45° bend for the creation of a horizontal branch, fitting for lock and screw-on cable trays of side height 35 mm. Screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.



St

Steel

FT

Hot-dip galvanised

## Master data

|                                    |                            |
|------------------------------------|----------------------------|
| Item number                        | 6036014                    |
| Type                               | RB 45 330 FT               |
| Description 1                      | 45° bend                   |
| Description 2                      | for cable tray, horizontal |
| Manufacturer                       | OBO                        |
| Dimension                          | 35x300                     |
| Colour                             | zinc                       |
| Material                           | Steel                      |
| Surface                            | Hot-dip galvanised         |
| Surface standard                   | DIN EN ISO 1461            |
| Smallest sales unit                | 1                          |
| Unit of quantity                   | Piece                      |
| Weight                             | 87.9 kg                    |
| Weight unit                        | kg/100 pc.                 |
| CO2 Footprint (GWP) Cradle-to-Gate | 2,7228 kg CO2e / 1 Piece   |


# Technical data sheet

45° bend 35 FT

Item number: 6036014



## Dimensions

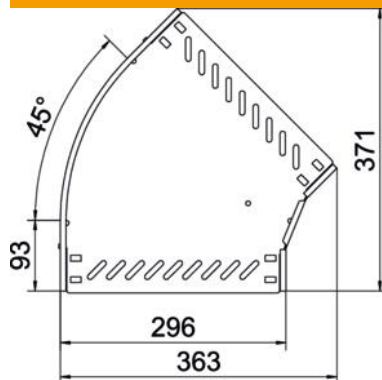

|                 |        |
|-----------------|--------|
| Width           | 300 mm |
| Height          | 35 mm  |
| Plate thickness | 0.8 mm |
| Dimension B     | 300 mm |

## Technical data

|                                         |                      |
|-----------------------------------------|----------------------|
| Bend (angle)                            | 45°                  |
| Connector version                       | Integrated connector |
| Type                                    | Bend, rigid          |
| Maintain electrical functions           | no                   |
| Material thickness, floor plate         | 0.8 mm               |
| Mounting perforation in base            | yes                  |
| NATO hole pattern                       | no                   |
| Change of direction                     | Horizontal           |
| Rustproof steel, pickled                | no                   |
| Side perforation                        | yes                  |
| Permitted temperature range, max.       | 120 °C               |
| Permitted temperature range, min.       | -20 °C               |
| Wide-span version                       | no                   |
| Type of connector, cable support system | Screwed              |
| Recommended quantity of bolts           | 10 St.               |
| Rail thickness                          | 1.25 mm              |