

Technical data sheet

Round conductor, galvanised steel

Item number: 5021103



- Can be used as a conductor and earthing conductor according to DIN EN 62561-2 (VDE 0185-561-2)
- Corresponds to the requirements of VDE 0185-305 (IEC 62305)
- RD 10 can also be used in the earth
- Zinc coating: $\geq 350 \text{ g/m}^2$ (approx. $50 \text{ }\mu\text{m}$ in mean value)



St

Steel

FT

Hot-dip galvanised

Master data

Item number	5021103
Type	RD 10
Description 1	Round conductors
Description 2	80 m ring
Manufacturer	OBO
Dimension	10mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	80
Unit of quantity	Metre
Weight	63 kg
Weight unit	kg/100 m


Technical data sheet

Round conductor, galvanised steel

Item number: 5021103



Dimensions

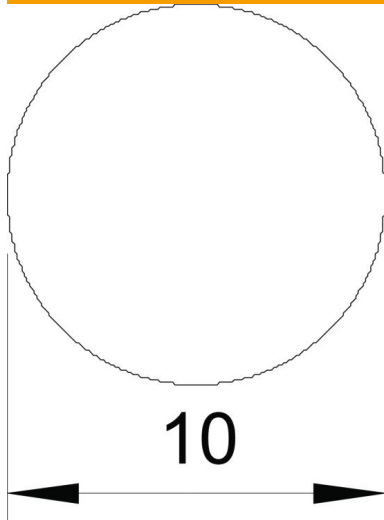

Dimension D	10 mm
-------------	-------

Technical data

Number of individual wires	1
High voltage-resistant, insulated version	no
Normal ring (ca. kg)	50
Normal ring (approx. m)	80
Length tolerance $\pm$	5 %
Cross-section	78 mm ²
Material property	Miscellaneous
Material jacket	Without