

Technical data sheet

Adjustable bend element, vertical 110 FS

Item number: 7005687



Adjustable bend element, vertical, for all cable tray types with a side height of 110 mm.
RGV 110 adjustable connectors should be ordered separately and in the appropriate quantity.




St	Steel
FS	Strip galvanized

Master data

Item number	7005687
Type	RGBEV 140 FS
Description 1	Adjustable bend element
Description 2	vertical
Manufacturer	OBO
Dimension	110x400
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	157.5 kg
Weight unit	kg/100 pc.

Dimensions

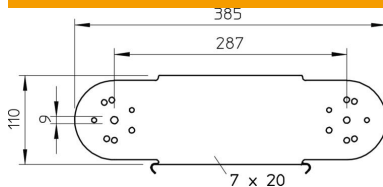

Width	400 mm
Width	16 in
Height	110 mm
Height	4 in
Plate thickness	1 mm
Dimension B	400 mm

Technical data sheet

Adjustable bend element, vertical 110 FS

Item number: 7005687



Technical data

Bend (angle)	Adjustable
Connector version	Without connectors
Type	Adjustable bend element
Maintain electrical functions	no
Mounting perforation in base	no
NATO hole pattern	no
Change of direction	Vertical, rising/falling
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Screwed