


# Technical data sheet

## Adjustable bend element, vertical 60 A4

Item number: 7075671

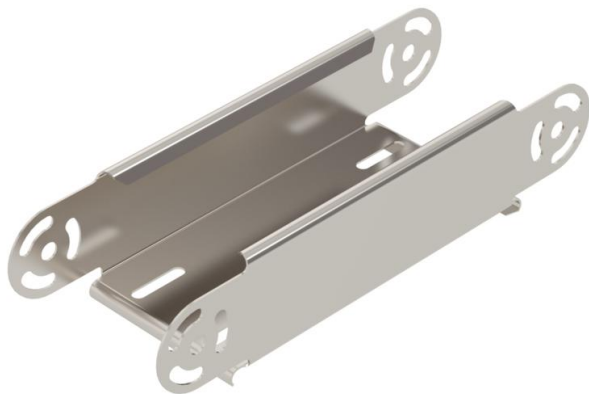

Adjustable vertical bend element, for all cable tray types with a side height of 60 mm.  
RGV 60 adjustable connectors should be ordered separately and in the appropriate quantity.  
Please order RGV 60 and SKS 8x16 hexagonal bolts separately.



|    |                 |
|----|-----------------|
| A4 | Stainless steel |
| 2B | Bright, treated |

### Master data

|                     |                         |
|---------------------|-------------------------|
| Item number         | 7075671                 |
| Type                | RGBEV 610 A4            |
| Description 1       | Adjustable bend element |
| Description 2       | vertical                |
| Manufacturer        | OBO                     |
| Dimension           | 60x100                  |
| Colour              | stainless steel         |
| Material            | Stainless steel         |
| Surface             | Bright, treated         |
| Surface standard    |                         |
| Smallest sales unit | 1                       |
| Unit of quantity    | Piece                   |
| Weight              | 54 kg                   |
| Weight unit         | kg/100 pc.              |


# Technical data sheet

## Adjustable bend element, vertical 60 A4

Item number: 7075671



### Dimensions

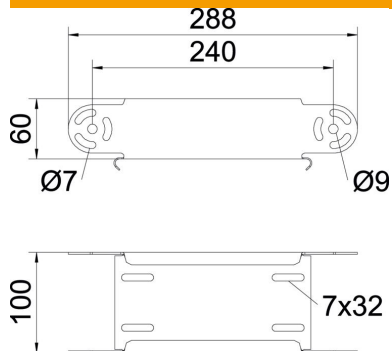

|                 |        |
|-----------------|--------|
| Width           | 100 mm |
| Height          | 60 mm  |
| Plate thickness | 1 mm   |
| Dimension B     | 100 mm |

### Technical data

|                                         |                          |
|-----------------------------------------|--------------------------|
| Bend (angle)                            | Adjustable               |
| Connector version                       | Without connectors       |
| Type                                    | Adjustable bend element  |
| Maintain electrical functions           | no                       |
| Mounting perforation in base            | no                       |
| NATO hole pattern                       | no                       |
| Change of direction                     | Vertical, rising/falling |
| Rustproof steel, pickled                | no                       |
| Side perforation                        | no                       |
| Permitted temperature range, max.       | 120 °C                   |
| Permitted temperature range, min.       | -20 °C                   |
| Wide-span version                       | no                       |
| Type of connector, cable support system | Screwed                  |